


Operation: DIP+SMT/沉板卧式 3.5 中型 音频连接器(SWITCH PIN)

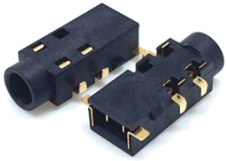

LTEM NO.:PJ-389 (Series)

(L14.3×W12.0×H5.0 3.5 PHONE-JACK)



沉板贴装

側向操作

精密部品

適合環保 RoHS


Technical parameter

LEVEL		A[better product]	B[average product]
PROJECT	Contact Rating	0.5A, 24V DC	
Electrical	Initial Contact Resistance	50mΩ max.	
	Insulation Resistance	100MΩ min.500V DC	Skey/PD: 100MΩ min.300V DC
Properties	Withstand Voltage	500V AC for 1 minute	350 V AC for 1 minut
	There No Load	6,000 Cycles	5,000 Cycles
Durable Performance	Rated Load	5,000 Cycles	4,000 Cycles
	Storage temp.	-35℃~+75℃(Operating Temp:)	
Operating Force		IF:5~15N MAX. (EF:10.0N MIN.)	
Heat Rrsistance		IR Reflow:255℃, 5sec. Manual:350℃, 3sec.	


Material declaration

No	NAME	Description
①	基座	PA66 (Black)耐热塑胶
②	接触端子#1	C5191R-H (t=0.20mm)磷铜[镍基银]
③	接触端子#1	C5191R-H (t=0.20mm)磷铜[镍基银]
④	接触端子#1	C5191R-H (t=0.20mm)磷铜[镍基银]
⑤	接触端子#1	C5191R-H (t=0.20mm)磷铜[镍基银]

CIRCUIT DIAGRAM

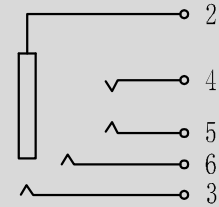

Unit:mm

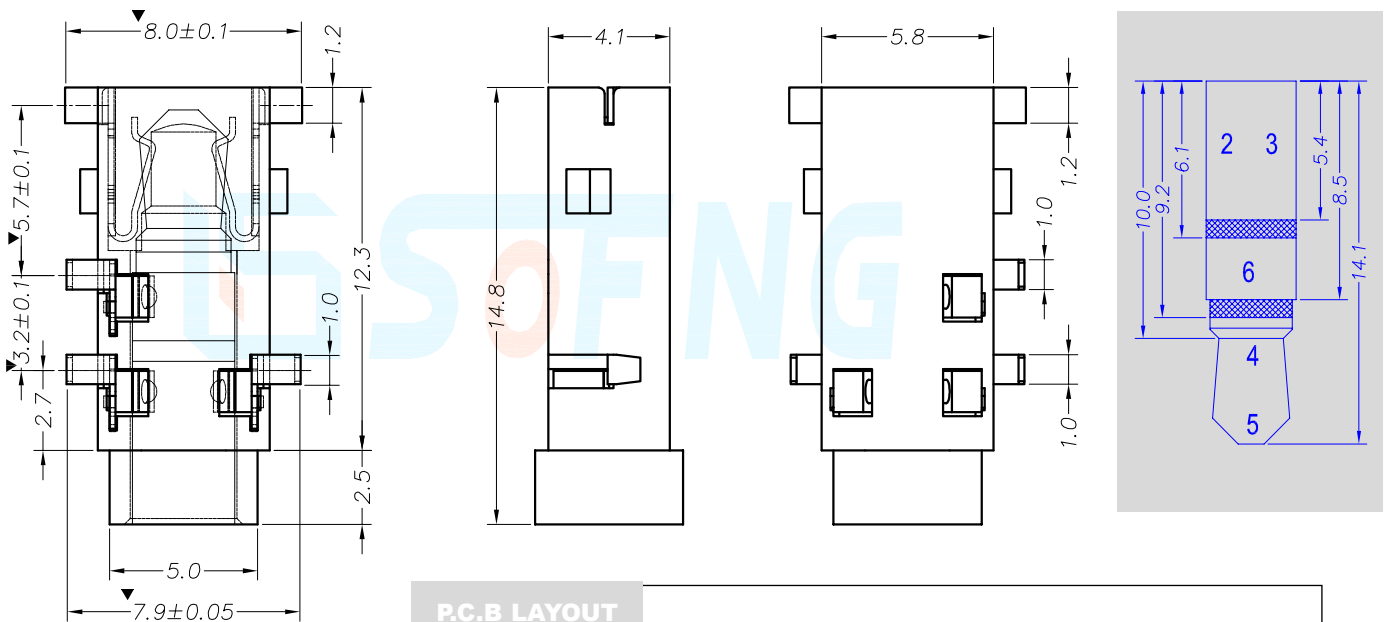

P.C.B LAYOUT

