

CONNECTORS

Operation: DIP/卧插式 3.5Ø中型 三段音频连接器/耳机插座



LTEM NO.: PJ-376 (Series)

(L16.5×W9.2×H10.7 3.5 PHONE-JACK)



插件卧式 DIP

側向操作

精密部品

带导向柱


適合環保 RoHS

Technical parameter

LEVEL		A[better product]	B[average product]
PROJECT	Contact Rating	0.5A, 24V DC	
Electrical	Initial Contact Resistance	50mΩ max.	
	Insulation Resistance	100MΩ min.500V DC	Skey/PD: 100MΩ min.300V DC
Properties	Withstand Voltage	500V AC for 1 minute	350 V AC for 1 minut
	There No Load	6,000 Cycles	5,000 Cycles
Durable Performance	Rated Load	5,000 Cycles	4,000 Cycles
	Storage temp.	-35℃~+75℃(Operating Temp:)	
Operating Force		IF:5~15N MAX. (EF:10.0N MIN.)	
Heat Rrsistance		225℃, 5sec. Manual: 350℃, 3sec.	

Material declaration		
No	NAME	Description
①	接觸端子#1	C5210 (t=0.40mm)黃銅[鍍基銀]
②	接觸端子#2	C5191R-H (t=0.30mm)磷銅[鍍基銀]
③	接觸端子#3	C5191R-H (t=0.40mm)磷銅[鍍基銀]
④	插口軸圈	H59 黃銅棒
⑤	基座	PBT (Black)耐熱塑膠

CIRCUIT DIAGRAM

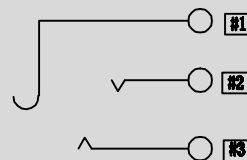

Unit:mm

