

Type ANM-UL Automotive Blade Fuse Miniature w/ UL Approval



www.optifuse.com (619) 593-5050

Specifications:

- **Voltage:** 32V DC
- **Amperage:** 2A, 3A, 4A, 5A, 7.5A, 10A, 15A, 20A, 25A, 30A
- **Body:** Nylon PA66
- **Terminals:** Zinc Alloy, Tin plated
- **Interrupt Rating:** 1000A @ 32V DC

Agency Standards and Listings:




Designed to meet ISO 8820-3 Standards.

Part Number	Amperage	Body Color	Voltage Drop
ANM-UL-2A	2A	Gray	225 mV
ANM-UL-3A	3A	Violet	200 mV
ANM-UL-4A	4A	Pink	200 mV
ANM-UL-5A	5A	Tan	175 mV
ANM-UL-7.5A	7.5A	Brown	150 mV
ANM-UL-10A	10A	Red	140 mV
ANM-UL-15A	15A	Blue	125 mV
ANM-UL-20A	20A	Yellow	125 mV
ANM-UL-25A	25A	Clear/White	125 mV
ANM-UL-30A	30A	Green	120 mV

Time Characteristics:		
% of Rated Current	Min Hold Time	Max Hold Time
110%	100h	
135%	750ms	1800s
200%	150ms	5s
350%	40ms	500ms
600%	20ms	200ms

Mechanical Dimensions: mm (Inches)

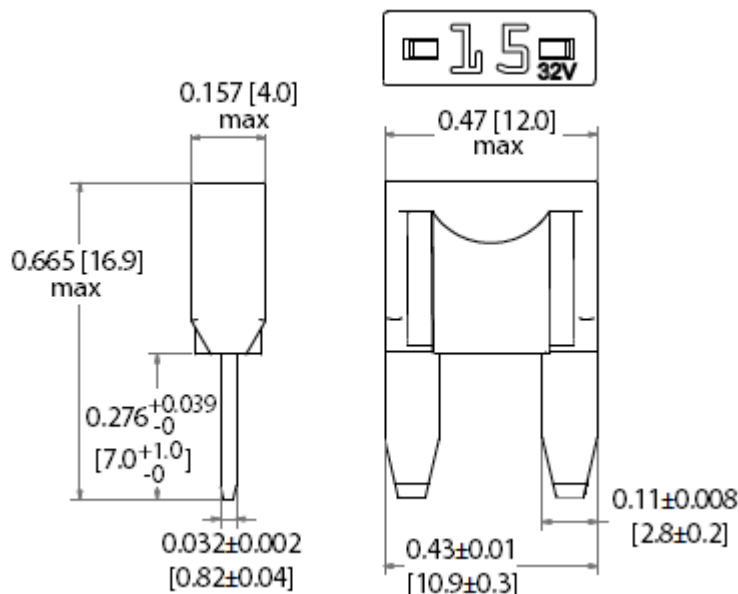

	<p>Warning: -Operation beyond the specified maximum ratings or improper use may result in damage and possible electrical arcing and/or flame.</p>
	<p>-Avoid contact of device with chemical solvent. Prolonged contact will damage the device performance.</p>