

Type ANT-UL Automotive Blade Fuse Tiny (Micro2 Style) w/UL Approval



www.optifuse.com (619) 593-5050

Specifications:

- **Voltage:** 32V DC
- **Amperage:** 5A, 7.5A, 10A, 15A, 20A, 25A, 30A
- **Body:** Nylon PA66
- **Terminals:** Zinc Alloy, Tin plated
- **Interrupting Rating:** 1000A @ 32 VDC


Agency Standards and Listings:



Part Number	Amperage	Body Color	Voltage Drop
ANT-UL-5A	5A	Tan	175 mV
ANT-UL-7.5A	7.5A	Brown	150 mV
ANT-UL-10A	10A	Red	140 mV
ANT-UL-15A	15A	Blue	125 mV
ANT-UL-20A	20A	Yellow	125 mV
ANT-UL-25A	25A	Clear/White	125 mV
ANT-UL-30A	30A	Green	120 mV

Time Characteristics:		
% of Rated Current	Min Hold Time	Max Hold Time
110%	100h	
135%	750ms	120s
160%	250ms	50s
200%	150ms	5s
350%	40ms	500ms
600%	20ms	100ms

Mechanical Dimensions: Inches [mm]

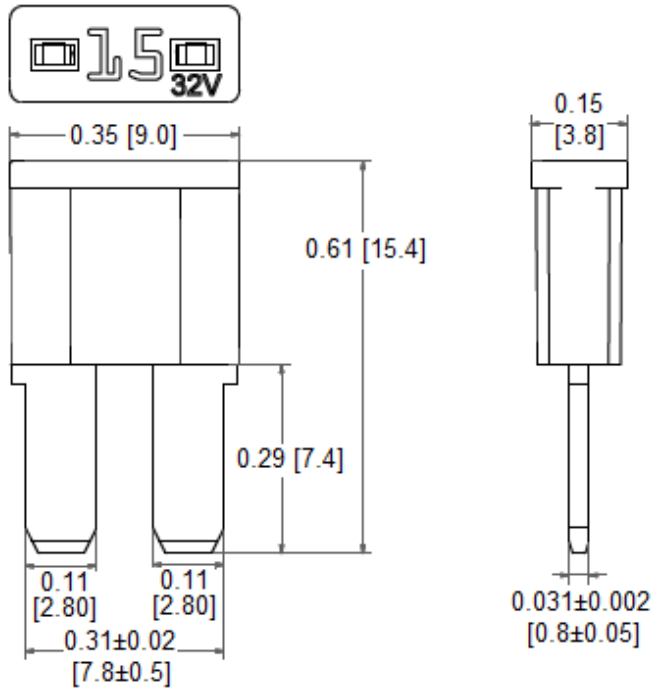

<p>Warning:</p>	-Operation beyond the specified maximum ratings or improper use may result in damage and possible electrical arcing and/or flame.
	-Avoid contact of device with chemical solvent. Prolonged contact will damage the device performance.