

# Type FSX

## Fast Acting Glass Tube Fuse

### Automotive Glass



www.optifuse.com (619) 593-5050

**Fuse Size:** 1/4" x 1" (6.3 x 25.4mm)

**Ampere Rating:** 250mA ~ 30A

**Voltage Rating:** 125V / 250V

**Electrical Characteristics:**


100%	135%	200%
Min.	Max.	Max.
4h	1h	120s

**Agency Standards and Listings:**



According to UL248-14

**Mechanical Dimensions: Inches[mm]**

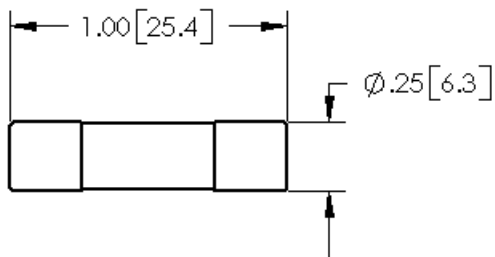

Part Number	Ampere Rating	Interrupt Rating	Voltage Rating	UL <sup>®</sup> US	CSA <sup>®</sup> US	PSE <sup>®</sup> JET
FSX-250mA	250mA	10KA @125VAC 35A @250VAC	125V/250V	●		
FSX-500mA	500mA			●		
FSX-750mA	750mA			●		
FSX-1A	1A	●		●		
FSX-1.25A	1.25A	10KA @125VAC 100A @250VAC		●		●
FSX-1.5A	1.5A			●		●
FSX-2A	2A			●		●
FSX-2.5A	2.5A			●		●
FSX-3A	3A			●		●
FSX-4A	4A	10KA @125VAC 200A @250VAC		●		●
FSX-5A	5A			●		●
FSX-6A	6A			●		●
FSX-7A	7A			●		●
FSX-8A	8A			●		●
FSX-10A	10A	200A @125VAC 200A @250VAC			●	●
FSX-12A	12A			●	●	
FSX-15A	15A			●	●	
FSX-20A	20A	100A @125VAC		●		
FSX-25A	25A			●		
FSX-30A	30A			●		

	<p><b>Warning:</b> -Operation beyond the specified maximum ratings or improper use may result in damage and possible electrical arcing and/or flame.</p>
	<p>-Avoid contact of Fuse device with chemical solvent. Prolonged contact may damage the device performance.</p>