


BL10-200X

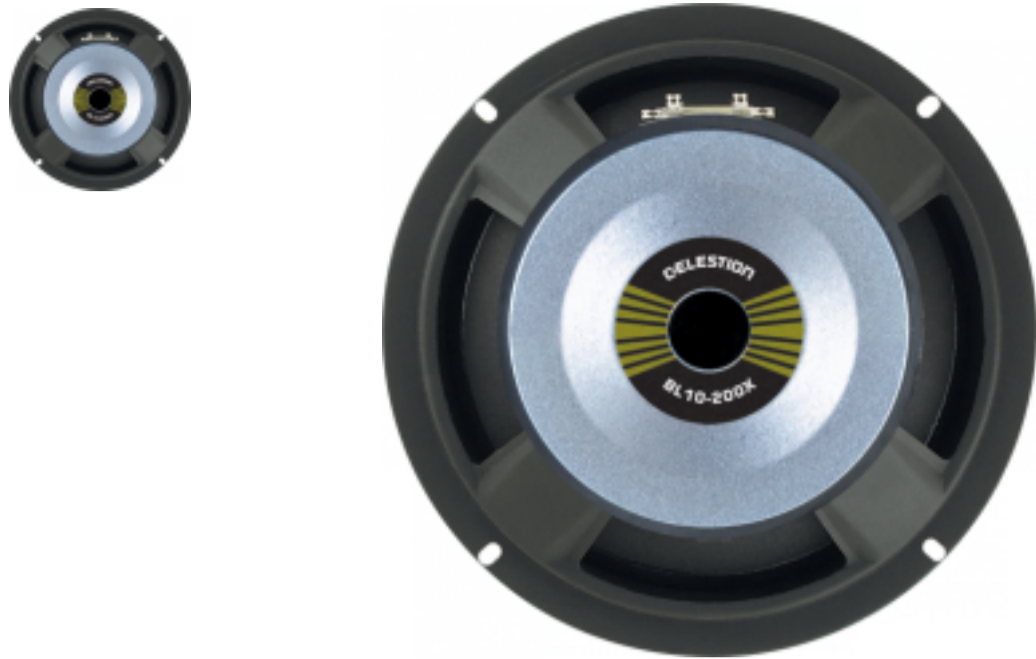


Not every player wants a super-clean, high-fidelity bass sound.

Characterised by an extended low end and greater linear excursion, Green Label speakers push out every note with a rich, warm tone and a powerful low-end thump.

Available with Ferrite or Neodymium magnets, Green Label speakers are primed for high-powered rock performances, where a full-bodied, warm, defined tone is essential.

8 Frequency Response

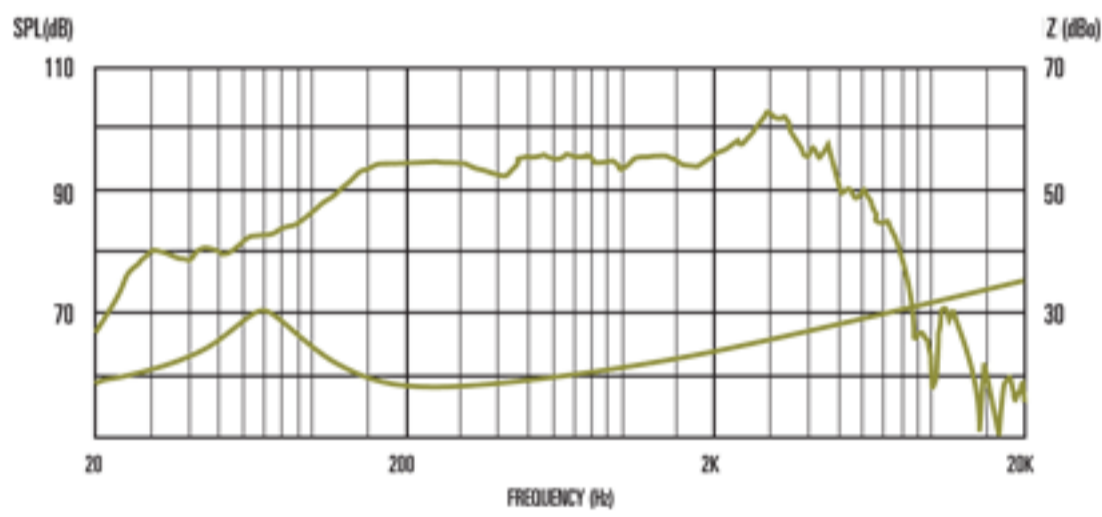

General Specifications

| | |
|--------------------------|---------------------|
| Nominal diameter | 254mm/10in |
| Power rating | 200Wrms |
| Nominal impedance | 8 |
| Sensitivity | 94dB |
| Magnet type | Ferrite |
| Voice coil diameter | 50.8mm/2in |
| Coil material | Copper |
| Cone material | Kevlar loaded paper |
| Former material | Polyimide |
| Surround material | Cloth-sealed |
| Frequency range | 45-3500Hz |
| Xmax | 4mm/0.15in |
| Gap depth | 8mm/0.31in |
| Voice coil winding width | 16mm/0.62in |

Small Signal Parameters

| | |
|--------------|-----------------------------|
| D | 0.21m/8.27in |
| Fs | 73Hz |
| Mair | 3.64g/0.128oz |
| Mmd | 31.95g/1.123oz |
| Qms | 3.58 |
| Qes | 0.56 |
| Qts | 0.48 |
| Re | 5.8 |
| Vas | 22.74lt/0.80ft ³ |
| Bl | 13.02Tm |
| Cms | 0.13mm/N |
| Rms | 4.55kg/s |
| Le (at 1kHz) | 0.92mH |

Mounting Information

| | |
|--------------------------|-----------------------|
| Cut-out diameter | 229mm/9in |
| Diameter | 256mm/10.1in |
| Mounting slot dimensions | 6 x 8mm/0.24 x 0.31in |
| Mounting slot PCD | 245mm/9.6in |
| Number of mounting slots | 4 |
| Overall depth | 110mm/4.3in |
| Unit weight | 3kg/6.6lb |