

Classic Lead




Developed in the late '70s, the Classic Lead uses a fibreglass voice coil former to deliver an 80W power rating and a unique dynamic sound.

A firm favourite with lead guitarists, the Classic Lead features a tightly controlled low-end, with strong high bass / low mid punch, aggressive mid range attack and a powerful yet controlled top-end.

For power chords it has the tone to make its presence felt but the subtle high-frequency roll-off makes it ideal for solos, able to project single notes on loud stages without becoming shrill.

8 Frequency Response

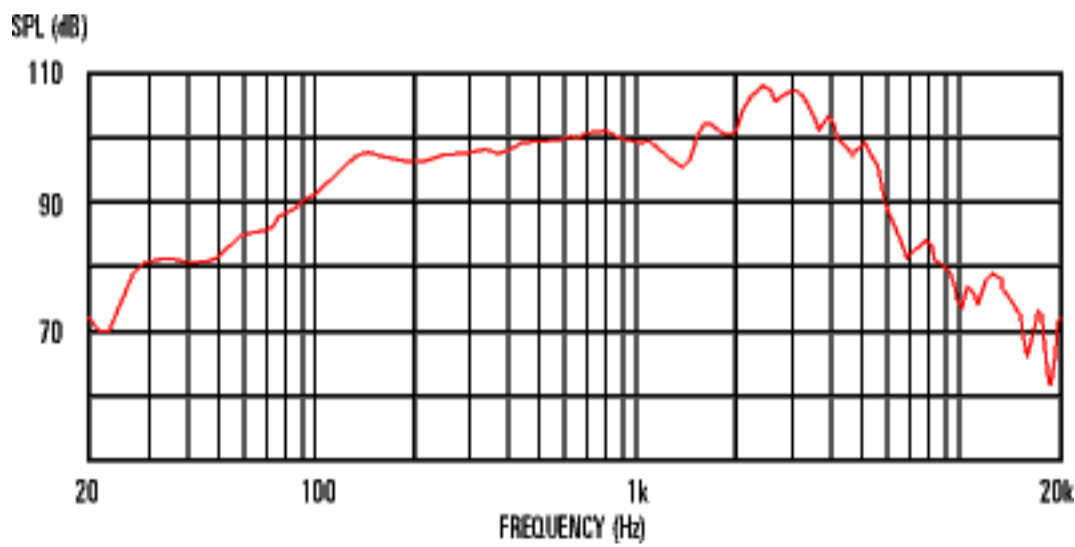

General Specifications

Nominal diameter	12", 305mm
Power rating	80Wrms
Nominal impedance	Available 8 or 16
Sensitivity	99dB
Chassis type	Pressed steel
Voice coil diameter	1.75", 55.5mm
Voice coil material	Round copper
Magnet type	Ceramic
Magnet weight	50oz, 1.42kg
Frequency range	80-5000Hz
Resonance frequency, Fs	85Hz
DC resistance, Re	Available 6.9 or 11.8

Mounting Information

Cut-out diameter	11.1", 283mm
Diameter	12.2", 309mm
Magnet structure diameter	6.1", 156mm
Mounting slot dimensions	0.31", 7.9mm Ø
Mounting slot PCD	11.7", 297mm
Number of mounting slots	4
Overall depth	5.3", 135mm
Unit weight	10.4lb, 4.7kg