


Heritage Series G12H(55)



It's hard to escape the sound of the G12H, just listen to any Hendrix recording and chances are you'll be hearing a whole raft of them powering the guitar out of the mix.

These faithful re-creations capture the unmistakable mojo of late 60s rock guitar tones. Unsurpassed in a 4x12 for cranking out towering, huge power chords, the Heritage Series G12H (55) features the 55c/s 'bass' cone. This model is famous for its thick syrupy tones, with a deep growling back end, densely complex mid-range and a finely detailed top end.

8 Frequency Response

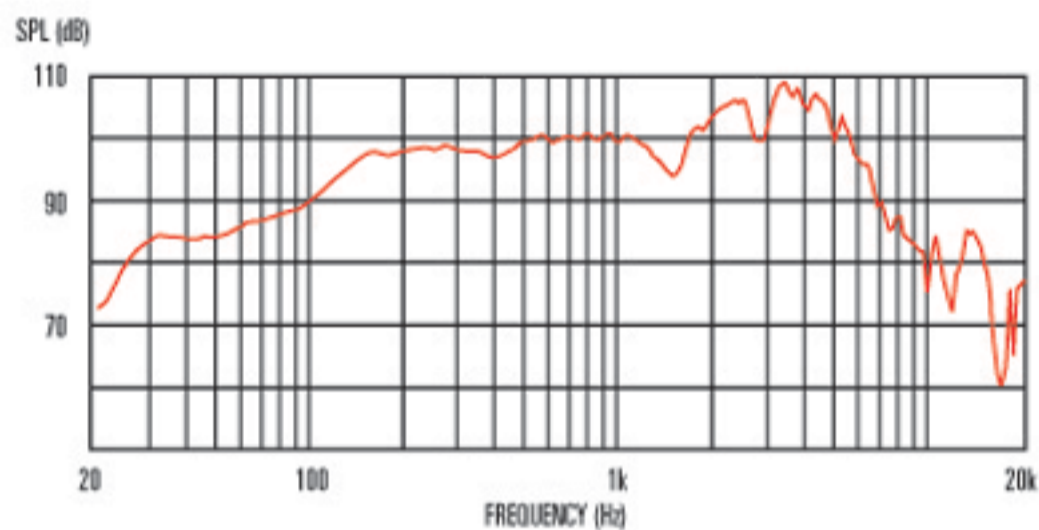

General Specifications

Nominal diameter	12", 305mm
Power rating	30Wrms
Nominal impedance	Available 8 or 15
Sensitivity	100dB
Chassis type	Pressed steel
Voice coil diameter	1.75", 44.5mm
Magnet type	Ceramic
Magnet weight	50oz, 1.42kg
Frequency range	55-5000Hz
Resonance frequency, Fs	55Hz
DC resistance, Re	6.53 and 12.11
Voice coil former material	Round copper

Mounting Information

Cut-out diameter	11.1", 283mm
Diameter	12.2", 309mm
Magnet structure diameter	6.6", 168mm
Mounting slot dimensions	0.31", 7.9mm Ø
Mounting slot PCD	11.7", 297mm
Number of mounting slots	4
Overall depth	5.3", 135mm
Unit weight	10.4lb, 4.7kg