


G12 Century Vintage



In developing the G12 Century Vintage we set out to use our Neodymium technology to design a modern speaker with a distinctly classic vibe. The result is a unique blend of extraordinary note definition and vintage character. Exceptionally lightweight and loud, with a tightly controlled low-end, the Century Vintage exhibits a clear, powerful mid-range and crisp, bright top-end. With super-fast attack and superb tracking, it's ideal for use in amps favoured by high-speed guitar players – both high gain rockers and clean country pickers.

8 Frequency Response

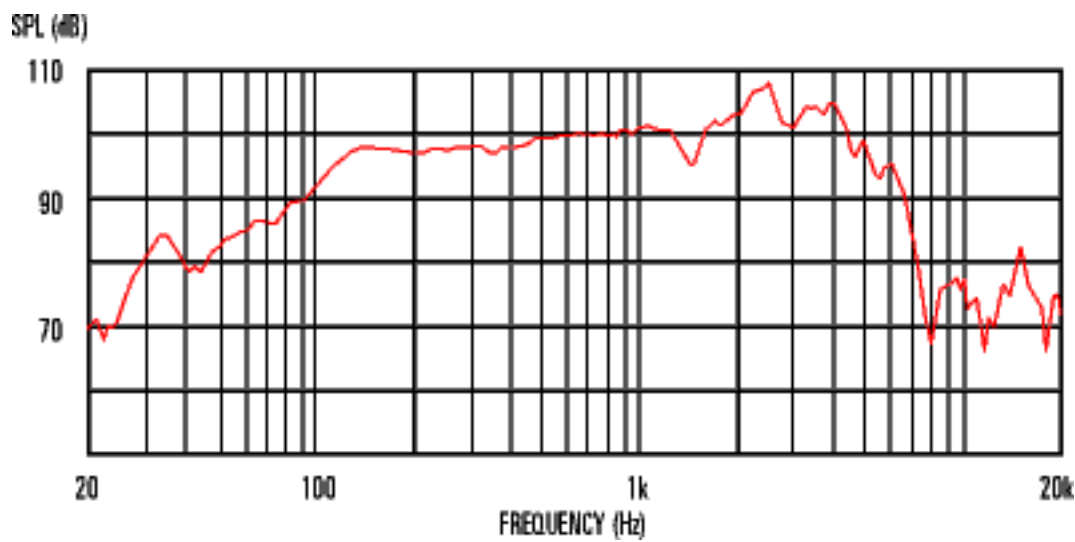

General Specifications

Nominal diameter	12", 305mm
Power rating	60Wrms
Nominal impedance	Available 8 or 16
Sensitivity	98dB
Chassis type	Pressed steel
Voice coil diameter	1.75", 44.5mm
Voice coil material	Round copper
Magnet type	Neodymium
Frequency range	75-5000Hz
Resonance frequency, Fs	70Hz
DC resistance, Re	6.88 or 13.35

Mounting Information

Cut-out diameter	11.1", 283mm
Diameter	12.2", 309mm
Magnet structure diameter	5.5", 140mm
Mounting slot dimensions	0.31", 7.9mm Ø
Mounting slot PCD	11.7", 297mm
Number of mounting slots	4
Overall depth	5.0", 128mm
Unit weight	3.7lb, 1.7kg