

G12H Anniversary




Originally re-released a little over a decade ago, the G12H remains hugely popular with players looking to recreate the classic sounds of 60s and 70s rock.

With a strong, aggressive low-end and powerful low-mids, the G12H penetrates any mix with an attacking upper mid-range and an ice-cool top-end. Used singly or in quartets it provides serious attitude to soft amp tones, easily cutting through loud stage levels for chord work, and imparting a hard edge to single notes.

A favourite in the 'boutique' amplifier market, the G12H is often used on its own or paired with a Celestion Blue or Gold for a full-bodied sound that adds ceramic attitude to the chime of an Alnico speaker.

8 Frequency Response

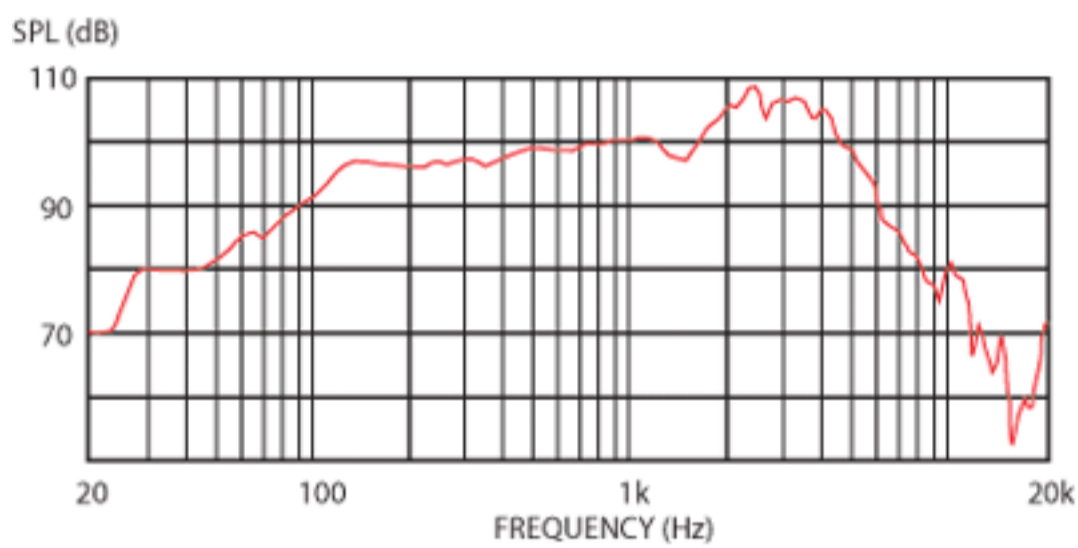

General Specifications

Nominal diameter	12", 305mm
Power rating	30Wrms
Nominal impedance	Available 8 or 16
Sensitivity	100dB
Chassis type	Pressed steel
Voice coil diameter	1.75", 44.5mm
Voice coil material	Round copper
Magnet type	Ceramic
Magnet weight	50oz, 1.42kg
Frequency range	75-5000Hz
Resonance frequency, Fs	85Hz
DC resistance, Re	6.7 and 13.1

Mounting Information

Cut-out diameter	11.1", 283mm
Diameter	12.2", 309mm
Magnet structure diameter	6.1", 156mm
Mounting slot dimensions	0.31", 7.9mm Ø
Mounting slot PCD	11.7", 297mm
Number of mounting slots	4
Overall depth	5.3", 135mm
Unit weight	10.4lb, 4.7kg