


ED3950/X

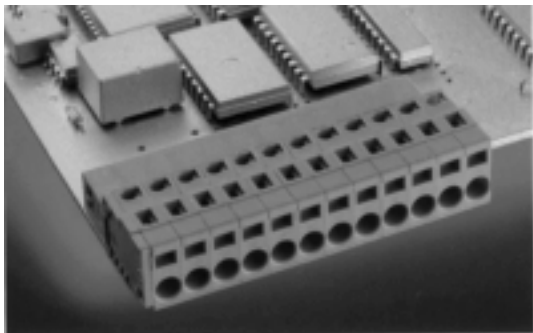

1-24 poles, Spacing 5.0 mm
 insert required no. of poles **X**
 How to order see page 5



Ratings:

Rated Voltage	300 V	250 V
Rated Current	15 A	12 A (T60)
Wire Size	AWG 28-12	2.5 mm²
Rating Impulse Voltage/Dirt Level		4 kV/3

Max. Rated Cross Section

Single Wire (solid)	2.5 mm²
Stranded Wire (flexible)	2.5 mm²
Stranded wire with Ferrules	1.5 mm²

Dimensions

Spacing	5.0 mm
Stripped Length	8.5 mm

Materials

Insulating Material	PA
Flammability Class	UL94 V-0
Temperature Range	-30°C/+105°C
Cage Clamp	Stainless Steel
Contact	Cu

Color

Green

