


SPECIFICATIONS

- Rated Voltage: 250V AC, DC
- Current rating: 7A-9A, AC, DC
- Withstanding Voltage: 1,500V AC/minute
- Insulation resistance: 1,000 Ω Min
- Temperature range: -40 °C to +105 °C
- Contact resistance: 20m Ω max

TERMINAL

. Part NO: CS-1149-T18 D DN T
 18: 低脚 (包AWG18#)
 T: 先镀后冲
 G: 镀半金镍1u"
 S: 先冲后镀亮锡
 DN: 紧接触点
 D: 大凸点

. Thickness: 0.20mm
 . Wire Range: AWG#18-AWG#24
 . Material: Phosphor bronze (C5191)
 . Finish: Tin Plated/Gold Plated
 . Reel Q' ty: 10,000PCS

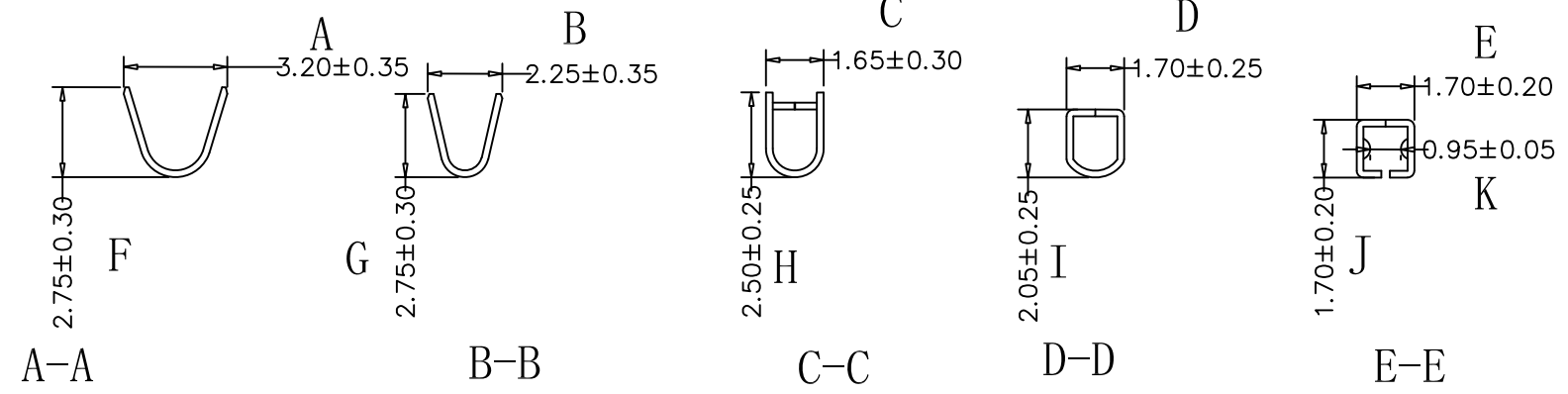

RoHS 2.0

本圖紙知識產權及版權由永丰盈有限公司所有, 未經書面許可不准擅自傳閱、复制和修改。本公司保留法律追究的权利。

类别	TERMINAL	品名	CS-1149-T18DDNT	X.	±0.50	材料	C5191-H	模号		SHEET 1 OF 1			
版本	C/0	设计	李文畅	X.X	±0.30	硬度	190° -210°	单位	mm	▲1	修改内容	修改日期	
制定部门	工程课	绘制	李文畅	X.XX	±0.20	画法		比例	1:1	▲1	卡点内折	203/09/01	
工程图号	CS-1149-T18DDNT	审核	黄海丰	X.XXX	±0.05	深圳市永丰盈电子有限公司 ShenZhenYongFengYing ELECTRONICS CO., LTD.						▲2	
制定日期	2023-09-01	核准	周中湖	X.XXXX	±0.01							▲3	

▲1	修改内容	修改日期
▲1	卡点内折	203/09/01
▲2		
▲3		