



**YX-A28-R943052-G0812**



**APPLICATIONS**

- Cross outlet
- Coil attached square diskette, size: 96\*52mm\*1.0mm (Adhesive backing)
- Double-sided magnetic tape
- Attach the coil to double-sided tape
- Double line tinning

**SHAPE & DIMENSIONS**

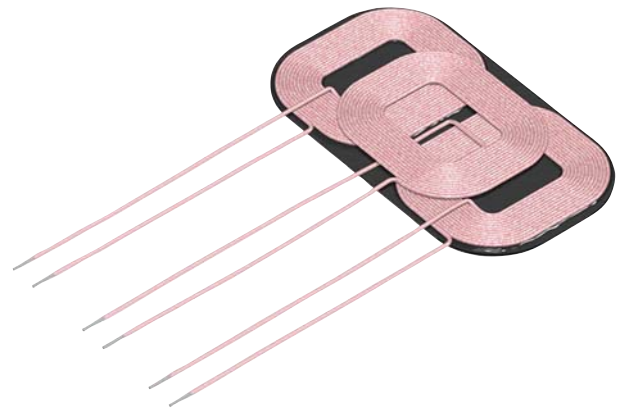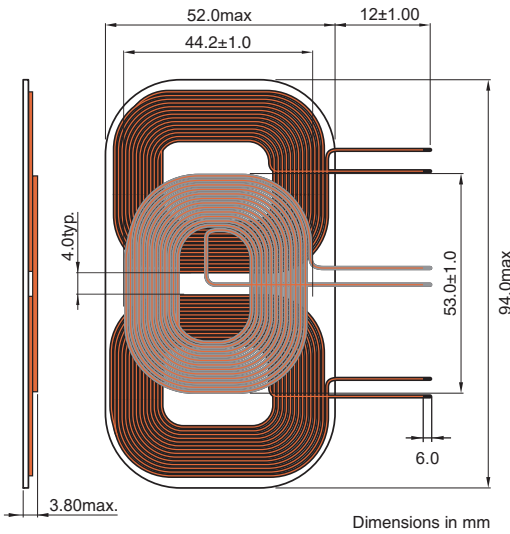

**AIR COIL SPECIFICATIONS**

Number of Coils	Wire Diameters	Turns Ratio
3	∅0.08mm x 105P	9T

**MAXIMUM RATINGS**

Operating Temperature / Humidity	Storage Temperature / Humidity
-40 to +85°C / 10 to 65% R.H.	-25 to +125°C / 10 to 65%

**ELECTRICAL CHARACTERISTICS**

OCL [100kHz 0.1V] (μH)	DCR [100kHz 0.1V] (mΩ)	WPC Compliant
6.30 ± 5%	34.00	Yes

**PACKAGING : BOX TYPE**

Dimensions (mm)		Quantity (pcs)	
Tray	3	Qty per tray	80
Small carton	320x320x55	Qty per small carton	3
Outer carton	350x350x180	Qty per outer carton	240

**OTHERS**

Weight (g) typ.	38.50
-----------------	-------