



Pre-assembled relay module PRS..., Screw connection, Consisting of: relay socket base, power contact relay, pluggable display/suppression module and holding clip, 2 CO contacts, Input voltage: 24 VDC

RAL: 9005

Business data

Article number	<u>15233.2</u>
Article name	PRSU 2G/24V DC
GTIN (EAN)	4044211046736
Packaging unit	10
Quantity unit	PC
Weight per piece (not including packaging)	57.5 g
Weight per piece (including packaging)	63.59 g
Unit of weight	G
Customs number	85364900
Country of origin	CN
Product description	Complete module
Colour	Black

Technical data

Dimensions

Length	76 mm
Width	16.6 mm
Height TS 35 / 7.5 with BA	71 mm

Ratings

Rated voltage Un	24 VDC -
Overvoltage category	III
Contamination degree	3

Connection data

Connection principle	Screw connection
Wire cross-section single core (rigid), min.	0.2 mm ²
Wire cross-section single-core (rigid), max.	2.5 mm ²
Wire cross-section stranded, min.	0.2 mm ²
Wire cross-section stranded, max.	2.5 mm ²
Wire cross-section stranded with wire-end ferrules, min.	0.2 mm ²
Wire cross-section stranded with wire-end ferrules, max.	1.5 mm ²
Stripping length	8 mm
Torque	0.8 Nm

Input data

Drop-out voltage	2,4 VDC
Operating range	ab 16,8 VDC
Power consumption	0,4 W

Output data

Switching voltage / switching voltage max.	250 / 400 VAC
Continuous current max. / Inrush current max.	8 / 15 A
Contact configuration	2 CO contacts
Switching capacity, max.	2000 VA
Electrical lifespan (AC1)	1x10 ⁵
Mechanical lifespan	30x10 ⁶
Bounce time at close of the NO/NC contact	6/8 ms

15233.2 PRSU 2G/24V DC

Technical data

Materials

Contact material	AgNi 90/10
Flammability class UL 94	V-0
Working temperature, min.	-40 °C
Working temperature, max.	70 °C

Further technical data

Degree of protection	IP20
Status display	✓
Insulation voltage coil/contact	1 kV
Free-wheel diode	✓
Response/release time	8 / 6 ms
Insulation voltage contact/contact	5 kV
Vibration resistance NO/NC	20/5 g
Pinning	5 mm
Coil and contact connections are separated	✓

Environmental Product Compliance

REACH Conform	yes
REACH Reference date	2023-06-14
REACH Candidate Substance Note	No
RoHS Conform	yes

Data sheet

15233.2 PRSU 2G/24V DC




Approvals

Standards and regulations

CE compliant	yes
--------------	-----

Media

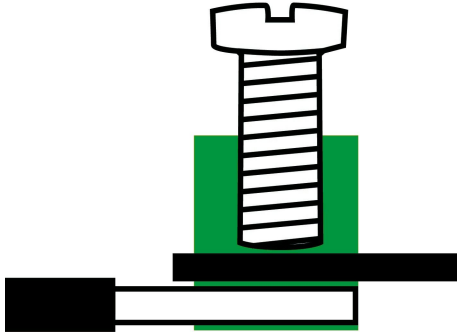

Accessories

Cross-connector



External cross-connector insulated, for relay socket base PRS 1 and PRS 2/6-pole, can be shortened, Voltage: 250 V, Current 10 A

Article number	Article name	GTIN (EAN)	Packaging unit
<u>15779.2</u>	AQI/PRS/8 BK	4044211134006	20 ST


Screwdriver



Screwdriver with bare blade, Colour: Black-grey

Article number	Article name	GTIN (EAN)	Packaging unit
<u>1086.0</u>	SDB 0,6x3,5	4044211014797	1 ST

Relays

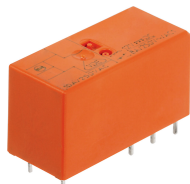

Plug-in miniature power relay, Encapsulated design with power contact, 2 CO contact, Input voltage: 24 VDC

Article number	Article name	GTIN (EAN)	Packaging unit
<u>6483.2</u>	PRS 2/24V DC	4044211074227	1 ST

Holding clamp



Relay holding clip, With eject, Suitable for relay socket base PRS 1 and PRS 2, for miniature power relays

Article number	Article name	GTIN (EAN)	Packaging unit
<u>15138.2</u>	PRS C1/2	4044211046217	1 ST

Insert modules

15233.2 PRSU 2G/24V DC



Insertion module, Suitable for relay socket base PRS, LED red status display, With free-wheel diode

Article number	Article name	GTIN (EAN)	Packaging unit
<u>15141.2</u>	PRS LED(RD) 24V DC	4044211046231	1 ST