



(PDB with CRPS Module inserted)

# FSP-FC210

## FSP-FC210E

### FEATURES

- A High Reliability PDB(power distribution board)
- CRPS Module Compatible
- 2U Narrow Form Factor
- Meet PMBus 1.2
- Design for 5,000 Meter above sea level
- High Reliability
- Low Ripple & Noise
- Over Current Protection
- Over Temperature Protection
- Over Voltage Protection

### DESCRIPTION

FSP-FC210/FSP-FC210E is a PDB(power distribution board) designed for CRPS (common redundant power supply) base on its standard. FSP-FC210 supports total power up to 2400 Watts, while FSP-FC210E supports 1200W. In addition, the PDB is featuring its short length and PMBus capability, ideally the best choice for datacenter, workstation, telecom applications.

### GENERAL SPECIFICATIONS

Dimension (L x W x H): 210 x 76 x 83.8 (mm)  
8.27 x 3 x 3.3 (inch)

Hold-up time at 100%: 12V = 11ms  
Loading 12Vsb = 70ms

Operating altitude: 5,000 meters above sea level

### OUTPUT RATING (FSP-FC210)

Output Power	Input Voltage	Current Range	DC Outputs				
			+3.3V	+5V	+12V	-12V	+5VSB
550W	100~240VAC	Min. Current	0A	0A	0.5A	0A	0A
		Max. Current	12A	24A	45.8A	0.3A	5A
		Combined Power	522W			3.6W	25W
800W	100~240VAC	Max. Current	12A	24A	65A	0.3A	5A
		Combined Power	772W			3.6W	25W
1200W	100~240VAC (1000W)	Max. Current	12A	24A	80.5A	0.3A	5A
		Combined Power	972W			3.6W	25W
	200~240VAC (1200W)	Max. Current	12A	24A	97A	0.3A	5A
		Combined Power	1172W			3.6W	25W
1600W	100~240VAC (1000W)	Max. Current	12A	24A	80.5A	0.3A	5A
		Combined Power	972W			3.6W	25W
	200~240VAC (1600W)	Max. Current	12A	24A	130.3A	0.3A	5A
		Combined Power	1572W			3.6W	25W





Output Power	Input Voltage	Current Range	DC Outputs				
			+3.3V	+5V	+12V	-12V	+5VSB
2000W	100~240VAC (1000W)	Max. Current	12A	24A	80.5A	0.3A	5A
		Combined Power	972W			3.6W	25W
	200~240VAC (2000W)	Max. Current	12A	24A	163.6A	0.3A	5A
		Combined Power	1972W			3.6W	25W
2400W	100~240VAC	Max. Current	12A	24A	80.5A	0.3A	5A
		Combined Power	972W			3.6W	25W
	200~240VAC (2400W)	Max. Current	12A	24A	196.7A	0.3A	5A
		Combined Power	2372W			3.6W	25W

**OUTPUT RATING (FSP-FC210E)**

Output Power	Input Voltage	Current Range	DC Outputs				
			+3.3V	+5V	+12V	-12V	+5VSB
550W	100~240VAC	Min. Current	0A	0A	0.5A	0A	0A
		Max. Current	12A	24A	45.8A	0.3A	5A
	800W	Combined Power	522W			3.6W	25W
		Max. Current	12A	24A	65A	0.3A	5A
		Combined Power	772W			3.6W	25W
	1200W	Max. Current	12A	24A	80.5A	0.3A	5A
		Combined Power	972W			3.6W	25W
		Max. Current	12A	24A	97A	3.6W	25W
		Combined Power	1172W			3.6W	25W

**MECHANICAL SPECIFICATIONS**

UNIT: mm

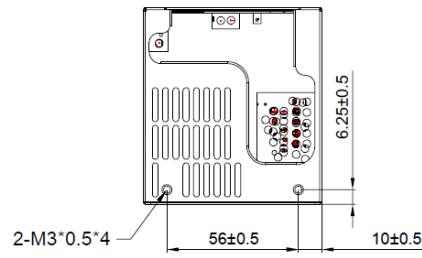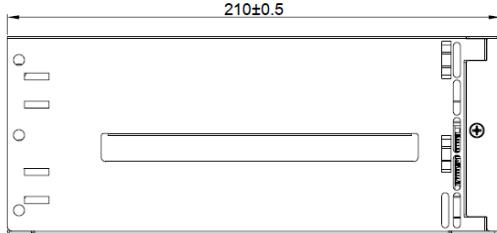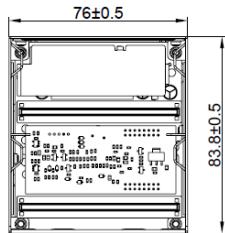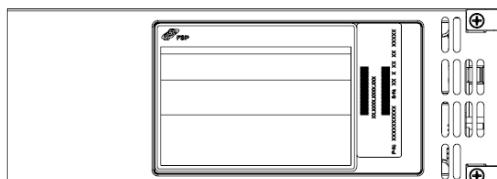

(Wire Harness is to be defined )