

OWS-434320TA-4A-W

High power speaker

High power, full range speaker optimized for wide bandwidth (180Hz to 20kHz) with a very linear frequency response and very low THD.




Characteristics

Size (ØxH) [mm]	43.0x22.1	
Sensitivity [dB SPL]	82.0±3 dB	1W/1m, free air
Impedance [Ω]	4	
Power [W]	4.0 / 4.0	nom / max, free air
F0 [Hz]	180	Free air
Termination	Terminals	


Specifications are subject to change without prior notice. Upon request Ole Wolff can supply further specifications, simulation parameters etc.

Mechanical drawing


Unless otherwise specified, tolerance: ±0.5 (unit: mm)

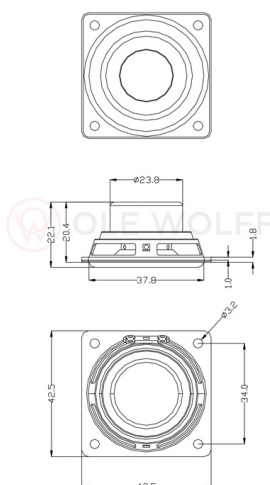

SPL

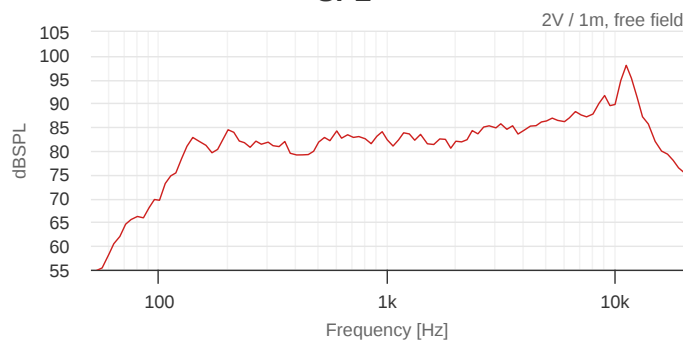

THD

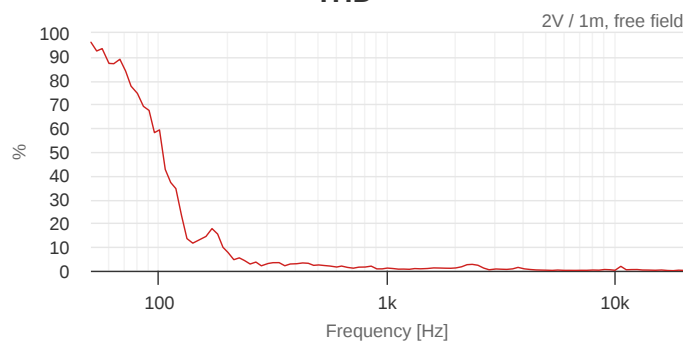

|Z|

