


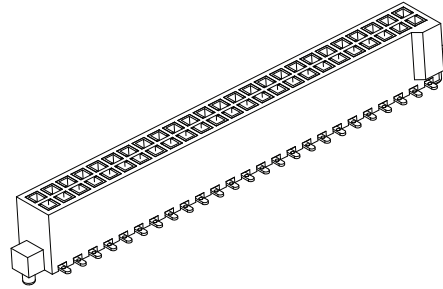


## .050" [1.27 mm] Contact Centers, Female Header, SMT with Posts- SFH Series Mates with SBH31 series (See opposite page)

### SPECIFICATIONS

- Operating Temperature: -40°C to +105°C
- Processing Temperature: 230°C Max. for 60 seconds,  
(260°C Max. for 10 seconds)
- UL Flammability Rating: 94V-0
- Contact Resistance: 20 milli Ohms Max.
- Current Rating: 1 Amp
- Dielectric Withstanding: 500 VAC
- Insulation Resistance: 5000 Megohms




### PART NUMBER OPTIONS

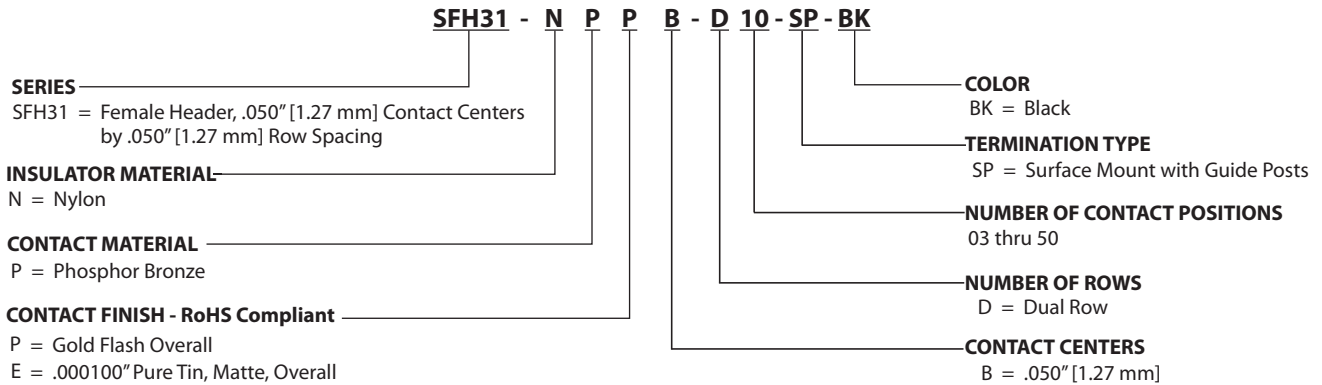

### DIMENSIONS For complete drawings, go to [www.sullinscorp.com](http://www.sullinscorp.com) or e-mail [techsupport@sullinscorp.com](mailto:techsupport@sullinscorp.com)

Dimensions in [ ] are in millimeters, all others are in inches.

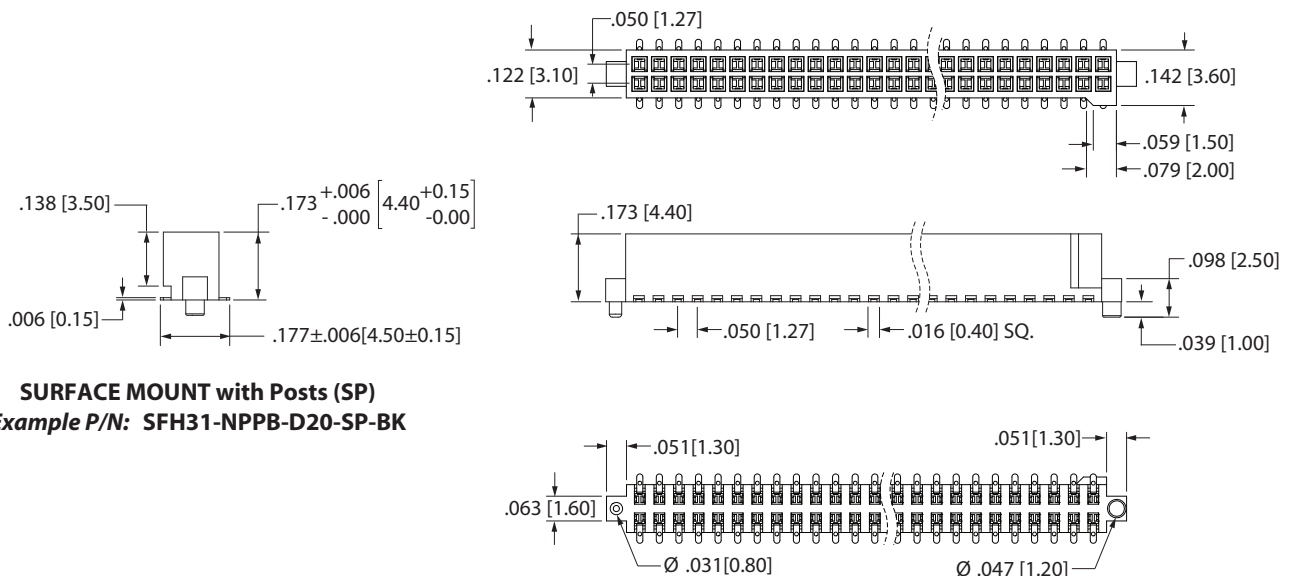

#### SURFACE MOUNT with Posts (SP)

Example P/N: SFH31-NPPB-D20-SP-BK