

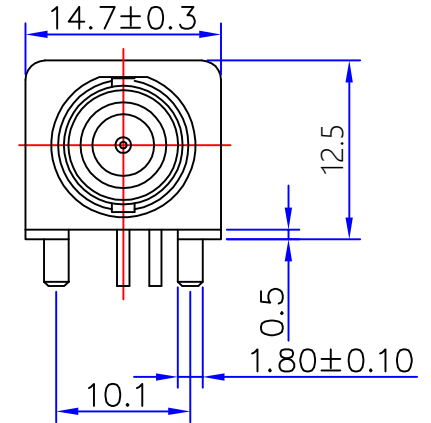


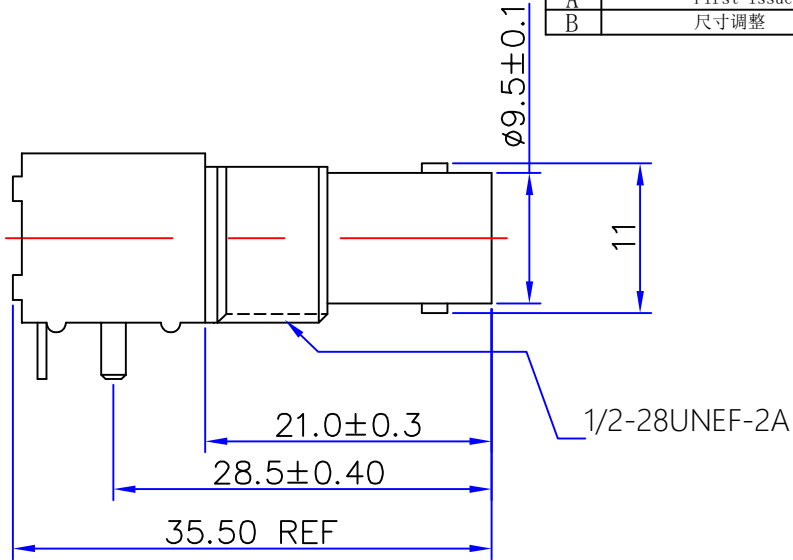



Kinghelm®

Product NO.		KH-801-0039		
REV	DESCRIPTION	DWN	DATE	APPROVEN
A	First issue	JIM	2012/11/02	John kine
B	尺寸调整	W.cheng	2020/05/05	John kine

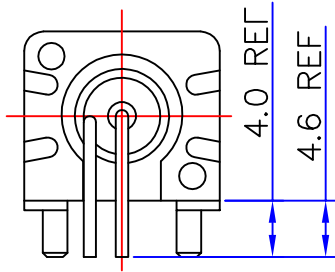

Specifications

Impedance: 75 Ohms
 Frequency Range: DC~3G
 VSWR: 1.3MAX
 Working Voltage: 500V rms @ sea level
 Insulation Resistance: 5000 Ohms min
 Temperature Range: -55°C TO +155°C
 Relative Humidity: ≤95% (40°C ±2°C)
 Drawings products are in line with ROHS standards

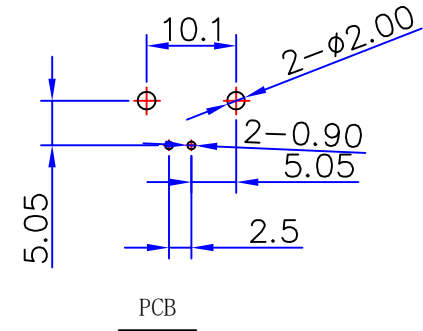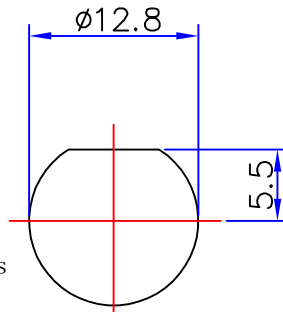

1	Body	Zinc	NI:80-120u"
2	Center contact	Brass	AU:1u"
3	Lead	Iron	AU:1u"
4	Fixed footrest	Iron	NI:80-120u"
5	Insulator	POM	White
6	Fixed mount	PBT	White
7	Washer	Brass	NI:80-120u"
8	Hex nut	Brass	NI:80-120u"
9			
10			
NO	Component Number	Material	Finish

NOTE:
 DRAWN: 贺骏驹
 CHECKED: 赖积任
 APPROVALS: 张松强
 DATE: 2012/11/10
 DATE: 12/04.2012

Tolerance	0-6 ±0.20 6-30 ±0.30 30-120 ±0.5 Angular ±2°
View	
UNIT	MM
SCALE	1:1

深圳市金航标电子有限公司		WWW.BDS666.COM	
KH-BNC75-3511		0755-83044319	
Name: BNC WHITE JACK CONNECTOR (12.5MM)			
SIZE A	Product NO.	REV B	
	KH-801-0039		
DateTime	CAD FILE	SHEET: 1 OF 1	
2012/11/02			

A B Kinghelm D E F G