


General Specification
 Current Rating: 1.5A DC /Contact, 20mA DC for LED signals
 Voltage Rating: 125V AC /Contact, 2.0 volts DC for LED signals
Operating Environment
 Standard Temperature: -20°C~+70°C
 Industrial Temperature: -40°C~+85°C
 Humidity: 20~70%
 Contact Resistance: ≤30mΩ
 Insulation Resistance: ≥500MΩ
 Dielectric Strength: 500V AC/(50HZ)/Min
 Mating And unmating Force: 3~20N
 Durability: 750 Cycles Min

Material Specification
 Housing :Thermo-plastic, UL94V-0.
 Contact :Alloy Copper
 Shield :Alloy Copper
 Please refer to the customer drawing when customer has specified

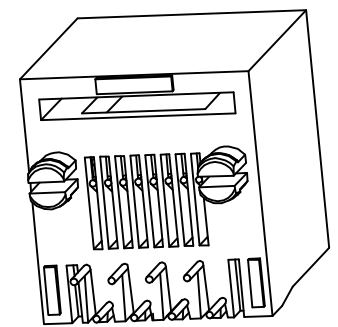

2	插针	PHOSPHOR BRONZE	8	FU"	
1	塑座	PBT	1	GREY	
序号	名称	材料	数量	镀层/颜色	备注

网络插座外形图



绘图: 魏飞 日期: 2022.11.05
 审核: 日期:
 核准: 日期:

一般公差	品名:	RJ45 (无耳)		
90~ ±0.25	料号:	5210-80000030PJ31 (WR02208)		
10~30 ±0.20	型号:	RJ45	图号:	
~10 ±0.16	角度:	±2°	版本:	
±0.10	单位:	mm	比例:	1:1
±0.05	纸张:	A4		
±0.02				
±0.01				

A/0 新出版发行

版次	变更履历	变更单号	绘制	日期	核准	日期
----	------	------	----	----	----	----