



**Ratings**

Rated Voltage 300V  
 Rated Current 15A  
 Rated Wire Size  
     solid AWG 22-12  
     flexible AWG 22-12

Screw Size M3


**Insulating Material**

Material PA 6.6  
 Flammability Class UL 94 V-0

**Materials**

Clamp Brass  
 Screw Steel  
 Solder Tag Bronze  
 Temperature Range -40° C ~ 105° C

RoHS Compliant

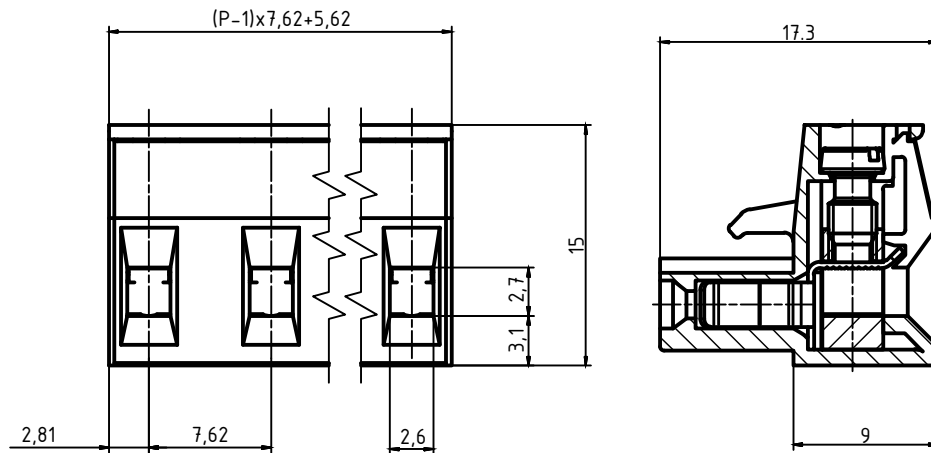

Part No.: **EDZ960/X**

No. of Poles  
 02 2 Poles  
 03 3 Poles  
 ... ..  
 16 16 Poles

DWG.	WF. Zhang	DATE	2017.09.11	UNITS:	MM	SHEET:	1 OF 1	Tolerance
CHK.	WF. Zhang	DATE	2017.09.11	SCALE:	NONE 5:1 ( : )	REV.:	A	X. ±0.50
APP.		DATE		TITLE:	EDZ960 series 7.62 mm			X.X ±0.30
				PART NO.	EDZ960/X			X° ±0.10
				DWG NO.	EDZ960/X.DWG			X° ±1°

SIGN	DESCRIPTION	CHK.	DATE

ON-SHORE TECHNOLOGY, INC.



Transfer or duplication of this document as well as the utilisation or communication of its content are not permitted unless express consent is granted. Violations give rise to claims for damages. All rights reserved in case of patent, utility model or design patent registrations.