

NOTES1:
UL Standard

1. Rated voltage/current : 300V / 12A
2. Withstanding voltage : AC:1600V/1Min.
3. Wire range : 28~14AWG

IEC Standard

1. Pollution degree	2	2	3
Overvoltage category	II	III	III
Rate impulse voltage(KV)	2.5KV	2.5KV	2.5KV
Rate voltage(V)	320V	200V	200V
Rate current(A)		17.5A	

2. Wire range : 0.2~1.5mm²

NOTES2:

1. Dimension shall be interpreted per ASME Y14.5-2009
2. Pitch : 3.50mm, Poles : N=02~24P
3. Stripping length : 8~9mm
4. Operating temperature: -40°C~+130°C
5. Undimensioned tolerances:

Pitch range in mm	Nominal dimension range in mm			Tolerance
	Over	TO	Under	
6	10	30	60	0.1/10
10	24	60	100	∠
15	30	60	150	±2'





6. RoHS Compliance

Ordering Information

JL212R-350 XX B 0 1

- Pitch 350=3.50PH
- No. of pins 2P~24P
- Housing Color: B=Black, G=Green, U=Blue, R=Red, W=White, Y=Yellow, D=Orange, E=Grey
- Packing: 0=Pe bag, T=Tube, A=Tray

Button color: White

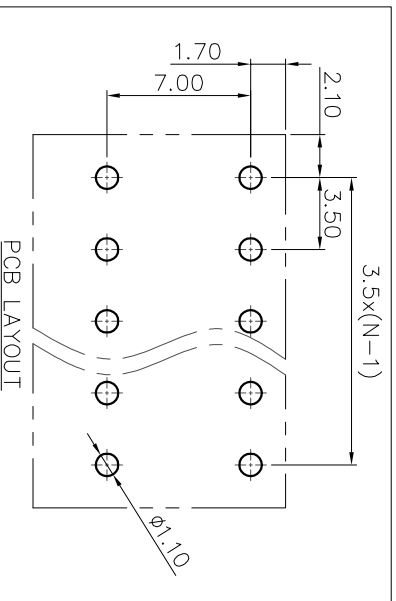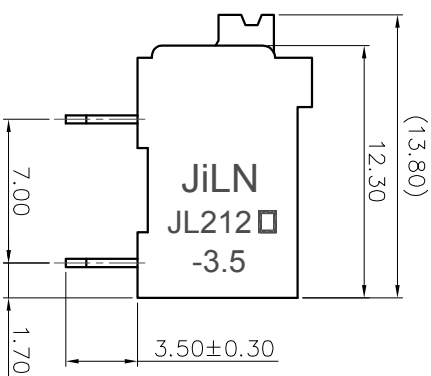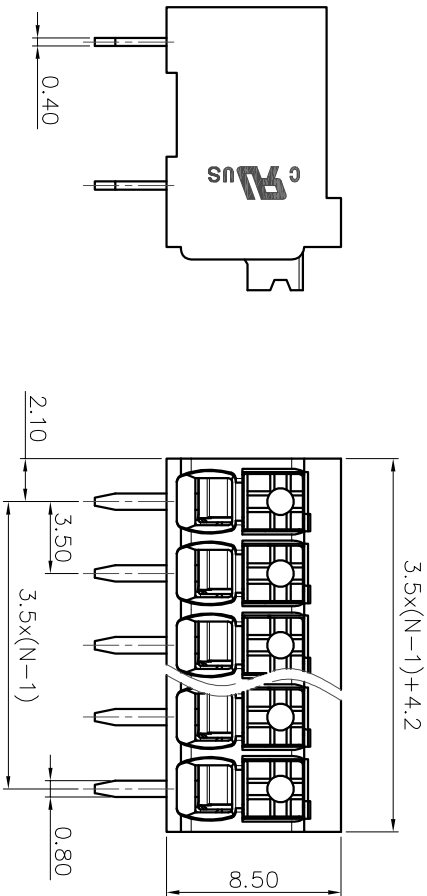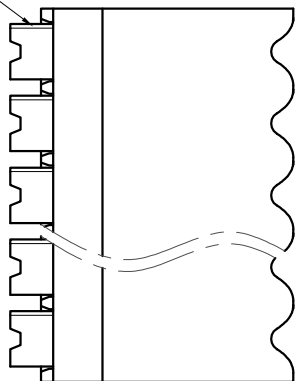

REVISION RECORD				
REV	ECN	DESCRIPTION	DRFT	DATE
A0		NEW		21.10.14

DRAW	SHUANGPING ZHENG		SCALE	FIT	PART NO.	JL212R-350XXB01
	UNIT	mm				
CHECK	LICHAD LIU		SIZE	A4	TITLE:	JL212R-THR-3-5-XXP 单簧式/弯脚/双排/黑色
	SHEET	1/1				
APPROVE	YONGLIANG GAO		PRD			

JILIN 东莞市锦凌电子有限公司
DONGGUAN JINLING ELECTRONIC CO., LTD