

P= 0.175mm



Back Flip




Low Profile

Features


- 1 Space saving, Ultra low profile
 - 0.175mm Pitch, 0.66mm Height, 3.52mm Mounting depth
- 2 High reliability
 - High FPC retention force with FPC side-catch design
 - Solder wicking and flux penetration prevention
- 3 User friendly design
 - Wide Tapers for smooth FPC insertion

Dimensions (16pos.)

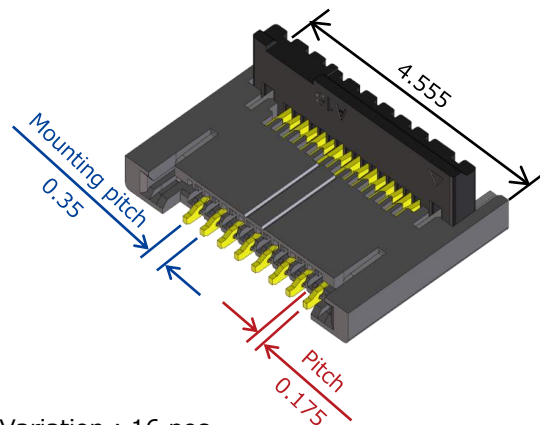


Actuator in a closed state

Unit : mm

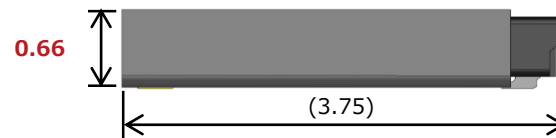

Actuator is fully opened

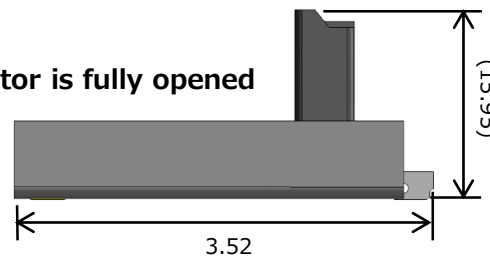

Specifications

Contact Resistance* ¹	300mΩ Max.
Withstanding Voltage	90V AC for 1 minute
Insulation Resistance	50MΩ Min. (100V DC)
Rated Current	0.15A
Rated Voltage	30V AC/DC
FPC Thickness	0.12±0.02mm

• RoHS compliant, Halogen-free product *²

*¹ FPC resistance is included.

*² This product satisfies halogen free requirements defined as 900ppm maximum chlorine, 900ppm maximum bromine, and 1,500ppm maximum total of chlorine and bromine.

※ Variation : 16 pos.