
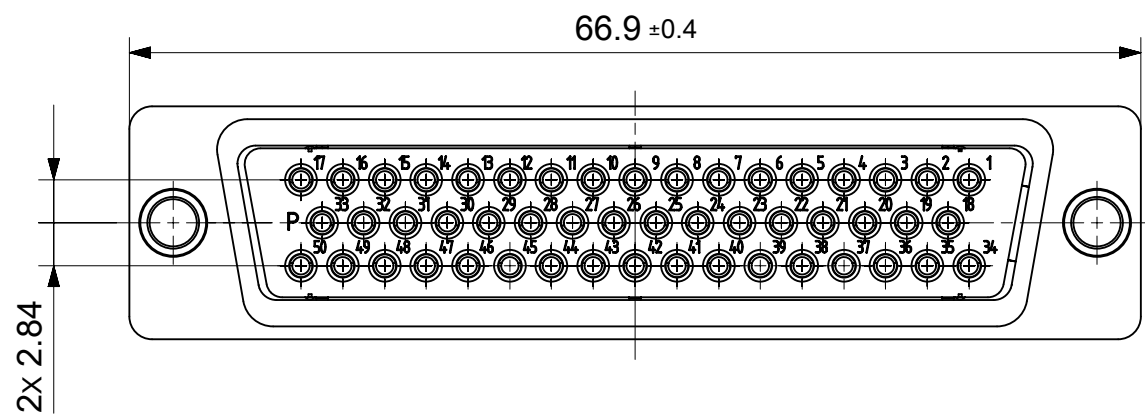
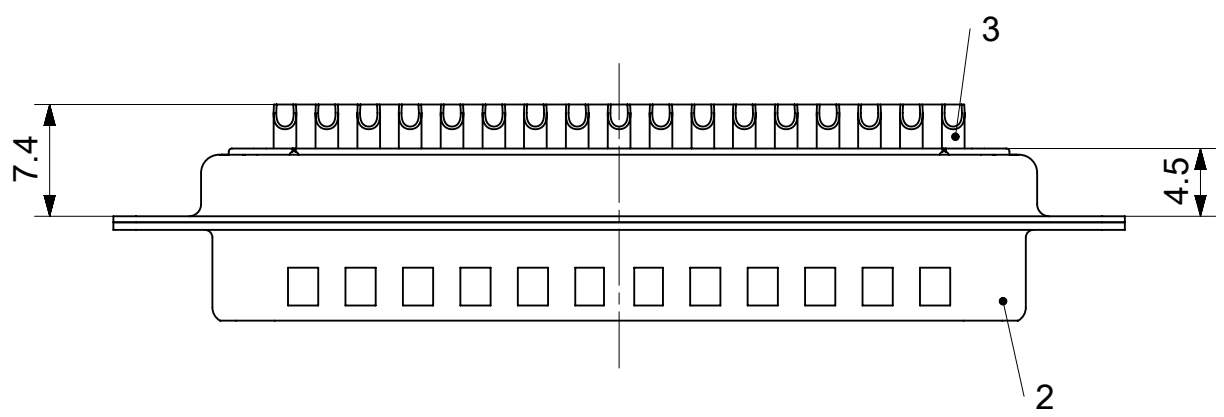
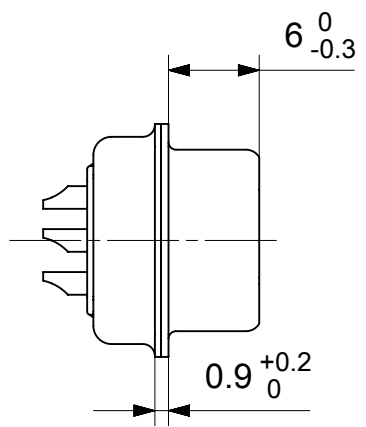


RoHS compliant
by exemption

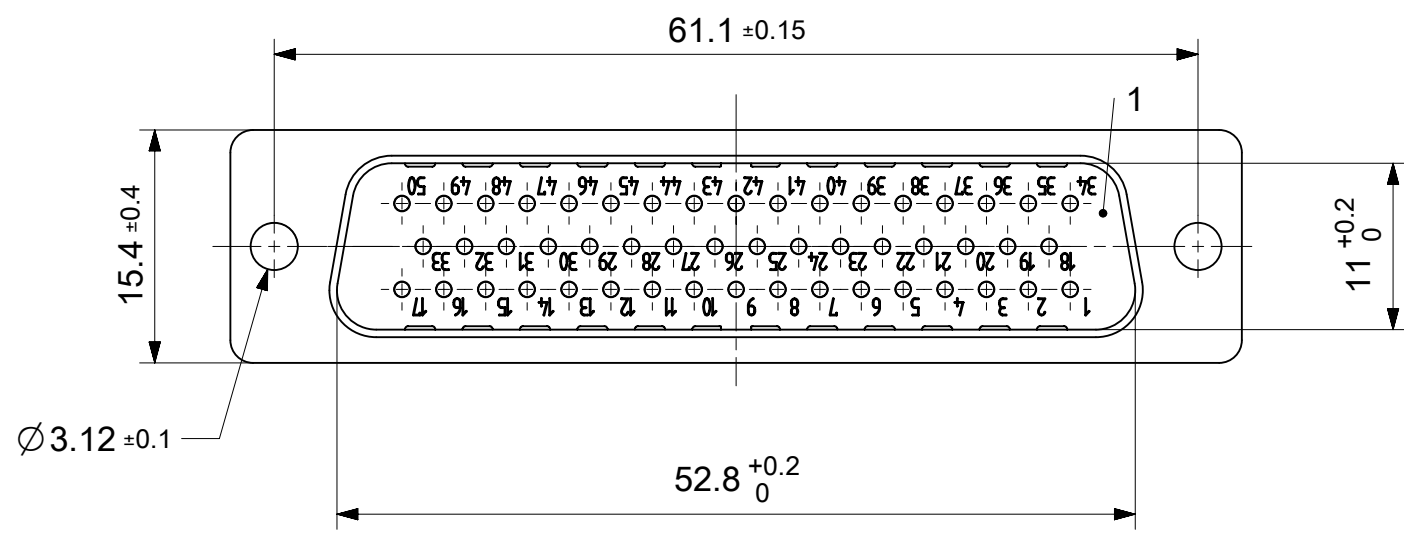

FCT Part number:
FH50P0Gy
 e.g FH50P0G1
 y for performance classes 1, 2 or 3
 (contact cycle for G1/G2/G3 = 500/200/50)

Material Number	y
1731090965	G1
1731090966	G2

No.	Pc.	Part	Type Description/Material	Surface plating/Color/Class
3	50	Signal contact	P0 / Brass	G1 / G2 / AWG 20
2	1	Shell	Steel	tin plated
1	1	Insulator	PCT (-55°C to +150°C)	natural

MEASUREMENTS WITHOUT TOLERANCE ACC TO ISO 2768-m			REPLACEMENT FOR DOCUMENT NUMBER: FH50P0Gy				
FUNCTIONAL SYMBOLS							
▽A = 0	mm	SCALE 2:1	CURRENT REV DESC:				
▽E = 0	GENERAL TOLERANCES (UNLESS SPECIFIED)		molex FCT D-SUB MINIATURE CONNECTOR PRODUCT CUSTOMER DRAWING				
▽F = 0	ANGULAR TOL ± °						
DIVISIONAL SYMBOLS		EC NO: 712973				2022/02/01	
4 PLACES ±		DRWN: SKANDB				2022/07/12	
3 PLACES ±		CHK'D: MTEUBEL				2022/07/12	
2 PLACES ±		APPR: MTEUBEL		2022/07/12			
1 PLACE ±		INITIAL REVISION:		DOCUMENT NUMBER	DOC TYPE	DOC PART	REVISION
0 PLACES ±		DRWN: SKANDB		1731090965	PSD	000	A
DRAFT WHERE APPLICABLE MUST REMAIN WITHIN DIMENSIONS		FIRST ANGLE PROJECTION	DRAWING	SERIES	MATERIAL NUMBER	CUSTOMER	SHEET NUMBER
			A3-SIZE	173109	SEE TABLE	GENERAL MARKET	1 OF 1