


产品详细信息 introduce

线对板连接器 >> Du Pont2.54

产品订购

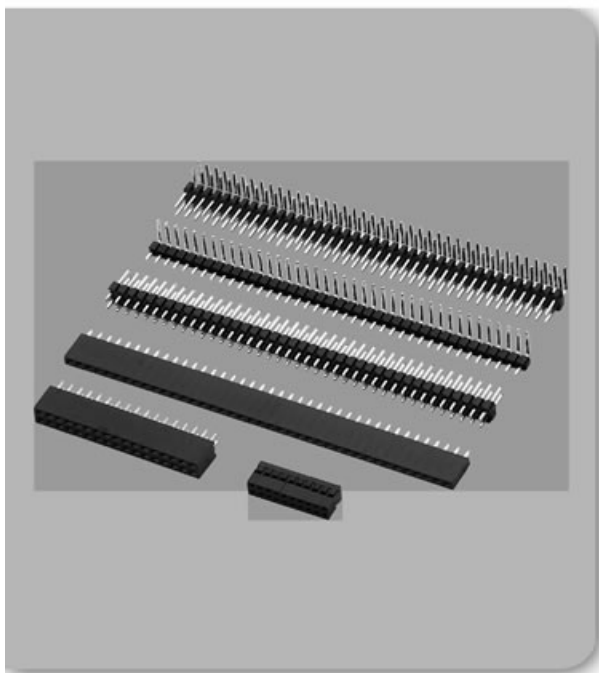


◆ SPECIFICATIONS

Unit:mm


- ◇ Poles: (YS)~35x2、(AS、WAS)2~40x2
- ◇ Applicable wire: AWG#22-#28
- ◇ Voltage rating: 250V DC/AC
- ◇ Current rating: 3.0A
- ◇ Withstand voltage: 800V AC
- ◇ Working Temperature: -25°C ~ +85°C
- ◇ Insulation resistance: ≥ 1000MΩ
- ◇ Contact resistance: ≤ 0.02Ω

UL:Recognized No.E309635  
 RoHS-specification and  
 Halogen-free products


Du Pont2.54 双排母

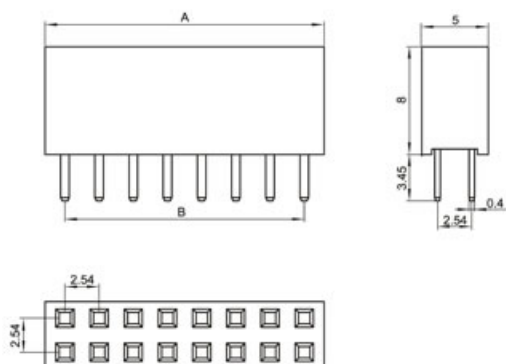


Du Pont2.54 单排母

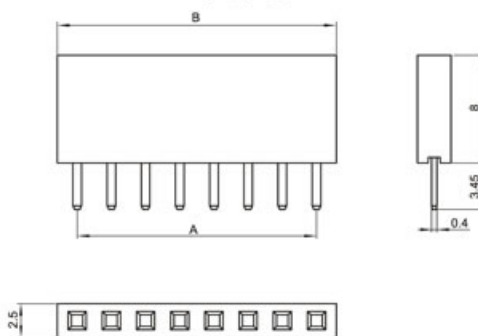


Du Pont2.54-nYS

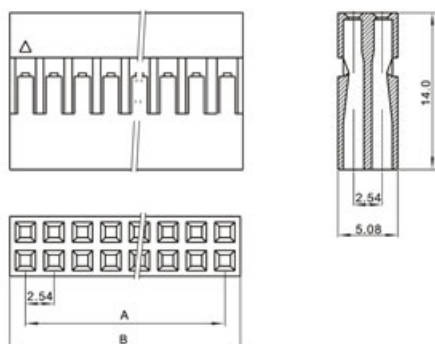


Du Pont2.54-nA

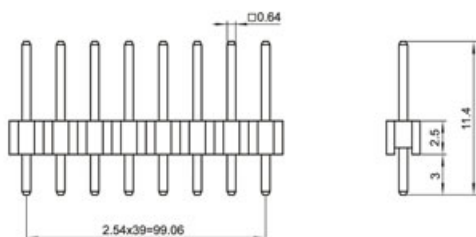




Du Pont2.54-2xnA

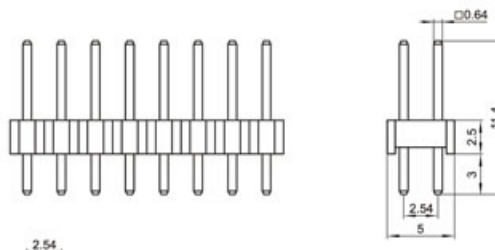




Unit:mm

 



**Du Pont2.54-nAW**

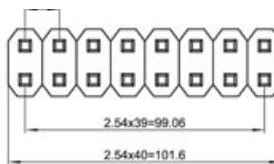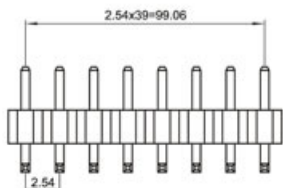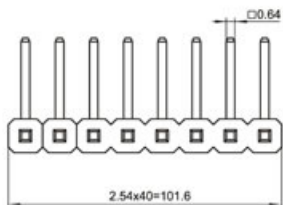

**Du Pont2.54-2xnAW**

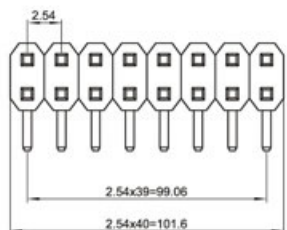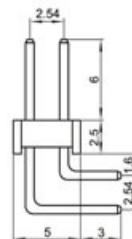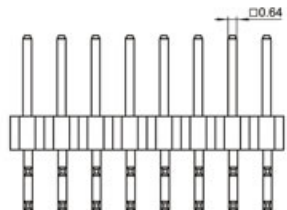

**Du Pont2.54-PT**

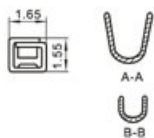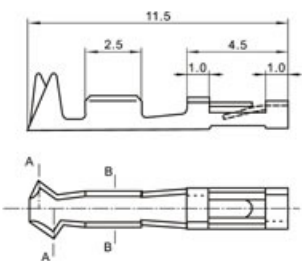

**Terminal(Du Pont2.54)**

Type	Applicable wires		O.D of wire ins mm	Material	Finish
	mm <sup>2</sup>	AWG#			
BM-Du Pont2.54	0.08-0.3	22-28	1.0-1.7	Phos.bronze	Tin-plated

Poles	Type	Size(mm)	
		A	B
4	Du Pont2.54-2x2YS	2.54	5.34
6	Du Pont2.54-2x3YS	5.08	7.88
8	Du Pont2.54-2x4YS	7.62	10.42
10	Du Pont2.54-2x5YS	10.16	12.96
12	Du Pont2.54-2x6YS	12.70	15.50
14	Du Pont2.54-2x7YS	15.24	18.04
16	Du Pont2.54-2x8YS	17.78	20.58
18	Du Pont2.54-2x9YS	20.32	23.12
20	Du Pont2.54-2x10YS	22.86	25.66
22	Du Pont2.54-2x11YS	25.40	28.20
24	Du Pont2.54-2x12YS	27.94	30.74

Poles	Type	Size(mm)	
		A	B
26	Du Pont2.54-2x13Y	30.48	33.28
28	Du Pont2.54-2x14Y	33.02	35.82
30	Du Pont2.54-2x15Y	35.56	38.36
32	Du Pont2.54-2x16Y	38.10	40.90
34	Du Pont2.54-2x17Y	40.64	43.44
36	Du Pont2.54-2x18Y	43.18	45.98
38	Du Pont2.54-2x19Y	45.72	48.52
40	Du Pont2.54-2x20Y	48.26	51.06
...	...	...	...
70	Du Pont2.54-2x35Y	86.36	89.16

点击次数: 1240 发布时间: 2010-6-14 【打印】 【返回】

