






东莞市宏聚电子五金制品有限公司

HONGJU(DONGGUAN)ELECTRONIC & METAL PRODUCTS CO.,LTD

FH1-208

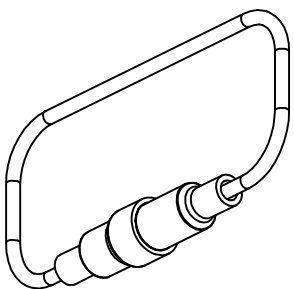

Fuse holder for overload protection
RoHS Compliant
 Rating: 10A 250VAC (UL,CUL,CQC,CE)
 Operating Temperature:-10°C~+85°C
 Dielectric Strength For: 2000V AC/1min
 Insulation Resistance: DC 500V 100MΩ min
 Fuse:Ø5.0x20mm
 Wire:18# AWG or 16# AWG UL 1015 105°C
 Wire Length:180mm

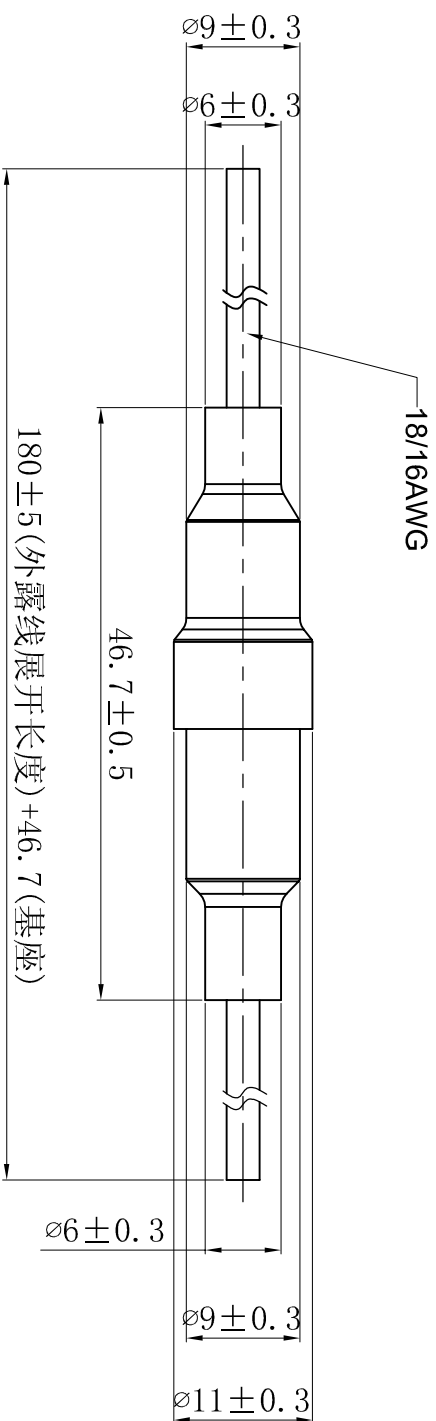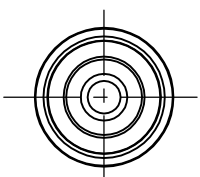

MATERIAL:

Housing:PBT, UL rated 94V-0
 Bayonet:PBT, UL rated 94V-0
 Terminal:Brass, or Brass tin plated
 Wire:UL 1015 AWM 18 AWG or 16 AWG

		公差 TOLERANCES		角度 ANGLE ±1°		单位 DIMENSION UNIT	
		.X±0.3 .XX±0.15		mm.			
		版本 VERSION	A1	比例尺 SCALE	NONE	品名 TITLE	图号 DRAWING NO
		核准 APPROVED BY		核对 CHECKED BY		FH1-208	FH1-208_A1
版本 VER.	重新整理发行	日期 DATE	2009.05.26	ECN NO.	N/A	绘图 DATE	2009.05.26
	变更说明 CHANGE DESCRIPTION					绘图人 DRAWN BY	黄雄阳